
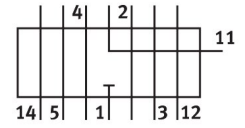


Vertical pressure supply plate VMPA2-VSP-0

Part number: 8029486

FESTO

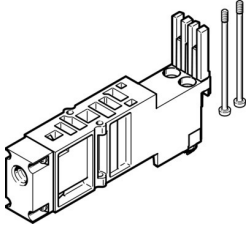

 General operating condition

Data sheet

| Feature | Value |
|--------------------------------|---|
| Grid dimension | 21 mm |
| Symbol | 00991883 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Pilot pressure | 0.3 MPa ... 0.8 MPa |
| Pilot pressure | 3 bar ... 8 bar |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:4:4] |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -5 °C ... 50 °C |
| Product weight | 70 g |
| Pneumatic connection, port 1 | G1/8 |
| Note on materials | RoHS-compliant |
| Material supply plate | PA-reinforced |