


# Suction cup insert OASI-10

Part number: 1048645

FESTO

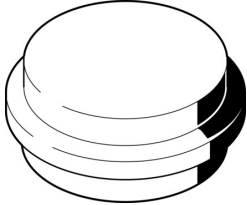

 [General operating condition](#)

## Data sheet

| Feature                      | Value   |
|------------------------------|---|
| Operating pressure           | 0 bar ... 0.95 bar                              |
| Operating medium             | Atmospheric air based on ISO 8573-1:2010 [7:::] |
| LABS (PWIS) conformity       | VDMA24364-A1-L                                  |
| For use in the food industry | See supplementary material information          |
| Ambient temperature          | 5 °C ... 50 °C                                  |
| Product weight               | 0.1 g   |
| Type of mounting             | Insertable                                      |
| Note on materials            | RoHS compliant                                  |
| Suction-cup insert material  | Protective grounding                            |
| Ejector pulse suitability    | 0 bar   |
| Mounting position            | Any   |