


# Stem actuated valve V/O-3-PK-3

Part number: 10747

FESTO

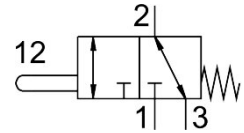

[PDF](#) General operating condition

## Data sheet

Feature	Value
Valve function	3/2, open/closed, monostable
Actuation type	Mechanical
Normal nominal flow rate (normalized to DIN 1343)	80 l/min
Pneumatic working port	PK-3
Operating pressure	0 bar ... 8 bar
Structural design	Piston seat
Nominal width	2.5 mm
Type of control	directly
Symbol	00991294
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Actuating force	17 N
Actuation force in initial position closed	17 N
Actuation force in initial position open	24 N
Product weight	20 g
Type of mounting	With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Seals material	NBR
Housing material	POM