


Swivel lever valve RW/O-3-PK-3

Part number: 10750

FESTO

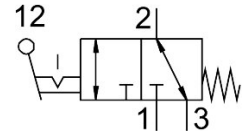

[PDF](#) General operating condition

Data sheet

| Feature | Value |
|---|--|
| Valve function | 3/2, open/closed, monostable |
| Actuation type | Mechanical |
| Normal nominal flow rate (normalized to DIN 1343) | 80 l/min |
| Pneumatic working port | PK-3 |
| Operating pressure | 0 bar ... 8 bar |
| Structural design | Piston seat |
| Nominal width | 2.5 mm |
| Type of control | Direct |
| Symbol | 00991285 |
| Operating medium | Compressed air as per ISO 8573-1:2010 [:-:-] |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C ... 60 °C |
| Type of mounting | With through-hole |
| Pneumatic connection 1 | PK-3 |
| Pneumatic connection 2 | PK-3 |
| Pneumatic connection 3 | PK-3 |
| Seals material | NBR |
| Housing material | POM |