


Pneumatic valve J-3-PK-3

Part number: 10772

FESTO

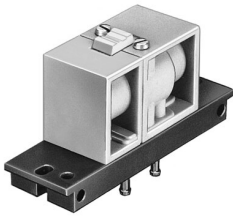

 General operating condition

Data sheet

Feature	Value
Valve function	3/2-way, bistable
Normal nominal flow rate (normalized to DIN 1343)	100 l/min
Pneumatic working port	PK-3
Operating pressure	-0.9 bar ... 8 bar
Structural design	Piston gate valve
Nominal width	2.5 mm
Symbol	00991377
Changeover time	7 ms
Explosion prevention and protection	Observe the information on the certificate Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 Zone III
Ambient temperature	-10 °C ... 60 °C
Product weight	75 g
Type of mounting	On sub-base On mounting frame With through-hole
Auxiliary pilot air port 12	PK-3
Auxiliary pilot air port 14	PK-3
Pneumatic connection 1	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Material of sub-base	Brass PPS-reinforced
Seals material	NBR
Housing material	Die-cast zinc