


Parallel kit EAMM-U-50-D32-42A-78-S1

Part number: 1202312

FESTO

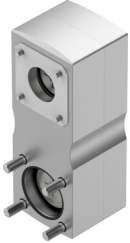

 [General operating condition](#)

Data sheet

Feature	Value
Size	50
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	12.1 kgmm ²
No-load driving torque	0.01 Nm
Transferable torque	1 Nm
Product weight	630 g
Interface code, actuator	D32B
Interface code, motor in	42A
Note on materials	RoHS compliant