


# Parallel kit EAMM-U-50-D32-42A-78-S1

Part number: 1202312

FESTO

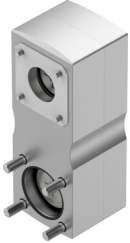

 [General operating condition](#)

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Size                     | 50                     |
| Mounting position        | Any                    |
| Gear ratio               | 1:1                    |
| Max. rotational speed    | 6000 rpm               |
| LABS (PWIS) conformity   | VDMA24364 zone III     |
| Storage temperature      | -25 °C ... 60 °C       |
| Relative air humidity    | 0 - 95 %               |
| Degree of protection     | IP65                   |
| Ambient temperature      | -10 °C ... 60 °C       |
| Mass moment of inertia   | 12.1 kgmm <sup>2</sup> |
| No-load driving torque   | 0.01 Nm                |
| Transferable torque      | 1 Nm                   |
| Product weight           | 630 g                  |
| Interface code, actuator | D32B                   |
| Interface code, motor in | 42A                    |
| Note on materials        | RoHS-compliant         |