


Pneumatic muffler AMTE-M-H-G18

Part number: 1206622

FESTO

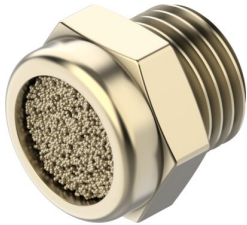

[PDF](#) [General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Mounting position | Any |
| Pack size | 20 |
| Symbol | 00991473 |
| Operating pressure | 0 MPa ... 1 MPa |
| Operating pressure | 0 bar ... 10 bar |
| Flow rate with respect to atmosphere | 615 l/min |
| Explosion prevention and protection | Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX) |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:-:-] |
| Information on operating and pilot media | Operation with oil lubrication possible |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Noise level | 92 dB(A) |
| Ambient temperature | -40 °C ... 80 °C |
| Product weight | 5 g |
| Pneumatic connection | G1/8 |
| Cushioning insert material | Bronze |
| Material of screwed plug | Brass |
| Note on materials | RoHS-compliant |