


Parallel kit EAMM-U-60-D32-60R-91

Part number: 1210434

FESTO

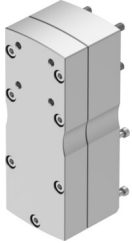

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Size | 60 |
| Mounting position | Any |
| Gear ratio | 1:1 |
| Max. rotational speed | 6000 rpm |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 26.7 kgmm ² |
| No-load driving torque | 0.07 Nm |
| Transferable torque | 3 Nm |
| Product weight | 1140 g |
| Interface code, actuator | D32B |
| Interface code, motor in | 60R |
| Note on materials | RoHS-compliant |