


# Sub-base VABS-C8-12XB-QX-B

Part number: 1236025

FESTO

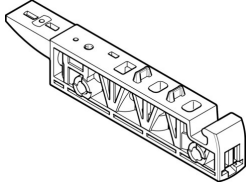

 [General operating condition](#)

## Data sheet

| Feature                                   | Value                   |
|---|-------------------------|
| Width                                     | 12 mm                   |
| Max. no. of valve positions               | 1                       |
| Corrosion resistance class (CRC)          | 0 - No corrosion stress |
| LABS (PWIS) conformity                    | VDMA24364-B1/B2-L       |
| Max. tightening torque for valve mounting | 0.48 Nm ... 0.72 Nm     |
| Max. tightening torque for wall mounting  | 1.3 Nm                  |
| Product weight                            | 15 g                    |
| Pilot air port 12/14                      | Prepared for cartridge  |
| Pneumatic connection 1                    | Prepared for cartridge  |
| Pneumatic connection 3                    | Prepared for cartridge  |
| Pneumatic connection 5                    | Prepared for cartridge  |
| Note on materials                         | RoHS compliant          |
| Manifold rail material                    | PA-reinforced           |