


# Sub-base VABS-C8-12XB-QX-DB

Part number: 1236028

FESTO

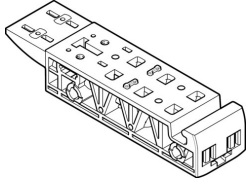

 [General operating condition](#)

## Data sheet

Feature	Value
Width	24 mm
Max. no. of valve positions	1
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.48 Nm ... 0.72 Nm
Max. tightening torque for wall mounting	1.3 Nm
Product weight	30 g
Pilot air port 12/14	Prepared for cartridge
Pneumatic connection 1	Prepared for cartridge
Pneumatic connection 3	Prepared for cartridge
Pneumatic connection 5	Prepared for cartridge
Note on materials	RoHS compliant
Manifold rail material	PA-reinforced