


Axial kit EAMM-A-D32-42A-S1

Part number: 1322179

FESTO

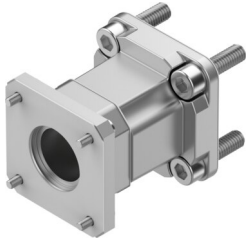

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	49.5 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.28 kgmm ²
Transferable torque	1.1 Nm
Product weight	140 g
Interface code, actuator	D32
Interface code, motor in	42A
Note on materials	RoHS-compliant