


# Clamping module EV-15/63-4

Part number: 13290

FESTO

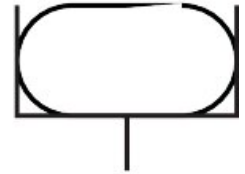

 General operating condition

## Data sheet

| Feature  | Value  |
|--|--|
| Stroke   | 4 mm   |
| Clamping area                                      | 15x63  |
| Mounting position                                  | Any  |
| Mode of operation                                  | Single-acting  |
| Symbol   | 00991208   |
| Operating pressure                                 | 0.2 MPa ... 0.6 MPa  |
| Operating pressure                                 | 2 bar ... 6 bar  |
| Operating pressure                                 | 29 psi ... 87 psi  |
| Operating medium                                   | Compressed air as per ISO 8573-1:2010 [7:-:-]  |
| LABS (PWIS) conformity                             | VDMA24364-B1/B2-L  |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper are excluded from use. This excludes printed circuit boards, cables, electrical connectors and coils. |
| Ambient temperature                                | -20 °C ... 40 °C   |
| Product weight                                     | 65 g   |
| Type of mounting                                   | With through-hole  |
| Pneumatic connection                               | M5   |
| Housing material                                   | Die-cast aluminum  |
| Diaphragm material                                 | TPE-U(PU)  |