


# Clamping module EV-20/120-5

Part number: 13292

FESTO

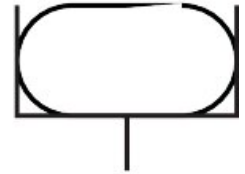

 General operating condition

## Data sheet

Feature	Value
Stroke	5 mm
Clamping area	20x120
Mounting position	Any
Mode of operation	Single-acting
Symbol	00991208
Operating pressure	0.2 MPa ... 0.6 MPa
Operating pressure	2 bar ... 6 bar
Operating pressure	29 psi ... 87 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper are excluded from use. This excludes printed circuit boards, cables, electrical connectors and coils.
Ambient temperature	-20 °C ... 40 °C
Product weight	190 g
Type of mounting	With through-hole
Pneumatic connection	M5
Housing material	Die-cast aluminum
Diaphragm material	TPE-U(PU)