


# Braking resistor CACR-LE2-72-W500

Part number: 1336611

FESTO

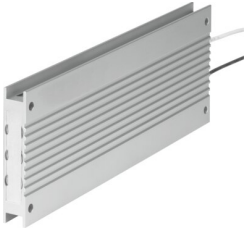

 [General operating condition](#)

## Data sheet

Feature	Value
Size	500
Mounting position	Open convection Vertical
Pulse energy braking resistor at 380 V	2000 Ws
Pulse energy braking resistor at 780 V	1800 Ws
Output at 35% duty cycle and 20°C	500 W
Braking resistor nominal power	200 W
Braking resistor nominal power at 380 V	150 W
Braking resistor nominal power at 780 V	120 W
Resistance value	72 Ohm
Certification	c CSA us (OL) c UL us - recognized (OL)
LABS (PWIS) conformity	VDMA24364 Zone III
Degree of protection	IP65
Ambient temperature	0 °C ... 50 °C
Product weight	550 g
Type of mounting	With through-hole With accessories
Note on materials	RoHS compliant