


# Mounting bracket PAML-MB-90-HP3

Part number: 1367323

FESTO

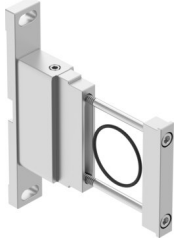

 [General operating condition](#)

## Data sheet

Feature	Value
Size	90
Nominal width DN	36
Series	L
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-10 °C ... 60 °C
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Product weight	300 g
Note on materials	RoHS-compliant
Seals material	NBR
Module connector material	Wrought aluminum alloy
Material of screws	Stainless steel
Bracket material	Wrought aluminum alloy