


# Barb fitting CRCN-1/8-PK-6

Part number: 13971

FESTO

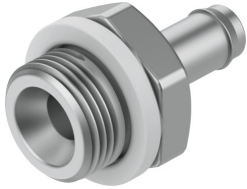

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal width	5.3 mm
Type of seal on screwed plug	Sealing ring
Pack size	10
Operating pressure for entire temperature range	-0.95 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
For use in the food industry	See supplementary material information
Ambient temperature	0 °C ... 60 °C
Product weight	7.5 g
Pneumatic connection 1	External thread G1/8
Pneumatic connection 2	for pneumatic tubing outside diameter 8 mm
Note on materials	RoHS-compliant
Housing material	High-alloy stainless steel
Material of threaded seal	PA-reinforced TPE-U(PU)