


End plate kit NEV-3DA/DB-NPT

Part number: 13997

FESTO

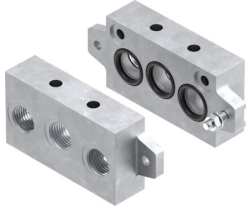

 [General operating condition](#)

Data sheet

Feature	Value
Width	190 mm
Operating pressure	0 bar ... 16 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Sub-base mounting type	With through-hole
Pneumatic valve mounting type	Screw-in
Pneumatic connection 1	NPT1-11 1/2
Pneumatic connection 3	NPT1-11 1/2
Pneumatic connection 5	NPT1-11 1/2