


Parallel kit EAMM-U-145-D80-140A-188-S1

Part number: 1433709

FESTO

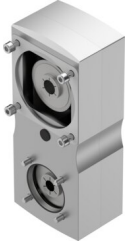

 [General operating condition](#)

Data sheet

Feature	Value
Size	145
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	4000 rpm
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	2270 kgmm ²
No-load driving torque	2 Nm
Transferable torque	50 Nm
Product weight	12100 g
Interface code, actuator	D80B
Interface code, motor in	140A
Note on materials	RoHS compliant