


Flange mounting EAHH-V2-80-R1

Part number: 1502306

FESTO

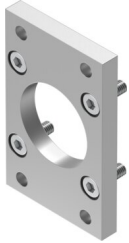

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|--|
| Size | 80 |
| Based on norm | ISO 15552 |
| Corrosion resistance class (CRC) | 3 - High corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Suitable for battery production with reduced Cu/Zn/Ni values (F1a) |
| Cleanroom suitability, measured according to ISO 14644-14 | Statically installed element, no meaningful evaluation possible according to ISO 14644-1 |
| Max. load capacity | 12 kN |
| Product weight | 1360 g |
| Note on materials | RoHS-compliant |
| Plate material | High-alloy stainless steel |
| Material of screws | High-alloy stainless steel |