


# Clamping module EV-16-4

Part number: 150682

FESTO

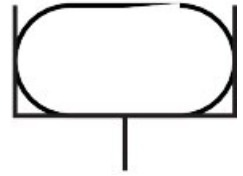

 General operating condition

## Data sheet

Feature	Value
Stroke	4 mm
Clamping area	Ø 16
Mounting position	Any
Mode of operation	Single-acting
Symbol	00991208
Operating pressure	≤0.6 MPa
Operating pressure	≤6 bar
Operating pressure	≤87 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 40 °C
Product weight	15 g
Type of mounting	With through-hole
Pneumatic connection	M3
Housing material	Die-cast aluminum
Diaphragm material	TPE-U(PU)