


Clamping module EV-20-4

Part number: 150683

FESTO

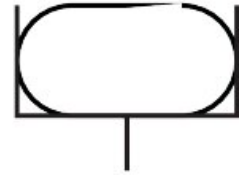

 General operating condition

Data sheet

| Feature | Value |
|------------------------|---|
| Stroke | 4 mm |
| Clamping area | Ø 20 |
| Mounting position | Any |
| Mode of operation | Single-acting |
| Symbol | 00991208 |
| Operating pressure | ≤0.6 MPa |
| Operating pressure | ≤6 bar |
| Operating pressure | ≤87 psi |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:-:-] |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C ... 40 °C |
| Product weight | 19 g |
| Type of mounting | With through-hole |
| Pneumatic connection | M3 |
| Housing material | Die-cast aluminum |
| Diaphragm material | TPE-U(PU) |