


Manifold sub-base with 90° connections NAVW-1/4-1-ISO

FESTO

Part number: 152789

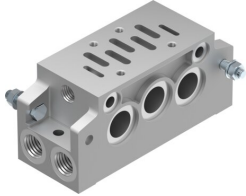

 General operating condition

Data sheet

| Feature | Value |
|--|---|
| Mounting position | Any |
| Conforms to standard | ISO 5599-1 |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:-:2] |
| Information on operating and pilot media | Ester oil < 0.1mg/m ³ , according to ISO 8573-1:2010 [-:-:2] |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -20 °C ... 80 °C |
| Temperature of medium | -10 °C ... 60 °C |
| Ambient temperature | -10 °C ... 60 °C |
| Product weight | 320 g |
| Sub-base mounting type | With through-hole |
| Type of mounting | With through-hole |
| Pilot air port 12/14 | G1/8 |
| Auxiliary pilot air port 12 | G1/8 |
| Auxiliary pilot air port 14 | G1/8 |
| Pilot air port 12 | G1/8 |
| Pilot air port 14 | G1/8 |
| Pneumatic connection 1 | G1/4 |
| Pneumatic connection 2 | G1/4 |
| Pneumatic connection 4 | G1/4 |
| Material of sub-base | Die-cast aluminum |