


# Clevis flange SUA-20

Part number: 157320

FESTO

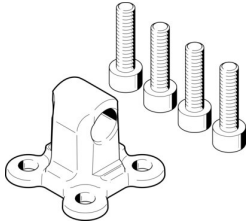

 [General operating condition](#)

## Data sheet

Feature	Value
Size	20
Mounting position	Any
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C ... 90 °C
Product weight	41 g
Note on materials	RoHS compliant
Mounting material	Wrought aluminum alloy
Bolt material	Steel, galvanized
Sleeve material	Spring steel
Material of bearing	Polymer
Material of screws	Galvanized steel
Fuse material	Spring steel
Shaft material	Steel With protective coating