


# Axial kit EAMM-A-R48-70A

Part number: 1578139

FESTO

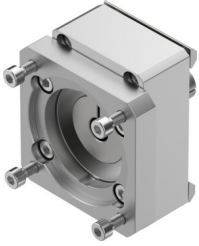

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	40.2 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	14.5 kgmm <sup>2</sup>
Transferable torque	4.4 Nm
Product weight	450 g
Interface code, actuator	R48
Interface code, motor in	70A
Note on materials	RoHS compliant