


Axial kit EAMM-A-D80-100A-S1

Part number: 1600673

FESTO

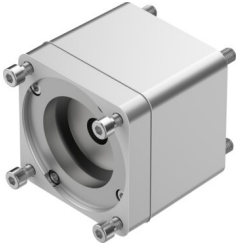

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	93.5 mm
Mounting position	Any
Max. rotational speed	5500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	128 kgmm ²
Transferable torque	60 Nm
Product weight	2030 g
Interface code, actuator	D80
Interface code, motor in	100A
Note on materials	RoHS-compliant