


Branching module PMBL-186-HP3-H

Part number: 1609073

FESTO

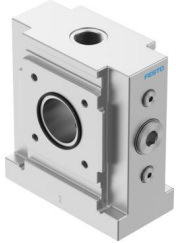

 General operating condition

Data sheet

Feature	Value
Nominal width DN	54
Series	L
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
CE marking (see declaration of conformity)	as per EU pressure equipment directive
UKCA marking (see declaration of conformity)	according to UK regulations for pressure equipment
Operating medium	Compressed air as per ISO 8573-1:2010 [:-::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-10 °C ... 60 °C
For use in the food industry	See supplementary material information
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Pneumatic connection 3	G1
Pneumatic connection 4	G1
Note on materials	RoHS-compliant
Seals material	NBR
Housing material	Wrought aluminum alloy