


# Clevis flange SNC-40

Part number: 174384

FESTO

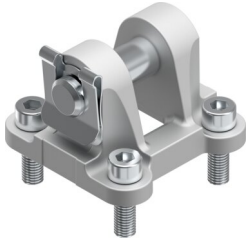

 [General operating condition](#)

## Data sheet

Feature	Value
Size	40
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	1.5 kN
Product weight	141 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Bolt material	Steel Galvanized
Material of screws	Steel Galvanized
Fuse material	Spring steel Galvanized