


# Clevis flange SNCB-40

Part number: 174391

FESTO

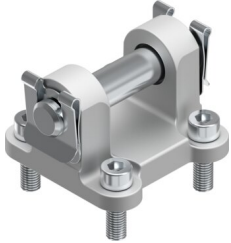

 [General operating condition](#)

## Data sheet

| Feature  | Value  |
|--|--|
| Size   | 40   |
| Based on norm                                      | ISO 15552  |
| Corrosion resistance class (CRC)                   | 1 - Low corrosion stress   |
| LABS (PWIS) conformity                             | VDMA24364-B2-L   |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper are excluded from use. This excludes printed circuit boards, cables, electrical connectors and coils. |
| Ambient temperature                                | -40 °C ... 90 °C   |
| Max. load capacity                                 | 1.5 kN   |
| Product weight                                     | 155 g  |
| Note on materials                                  | RoHS compliant   |
| Mounting material                                  | Die-cast aluminum  |
| Bolt material                                      | Steel, galvanized  |
| Material of bearing                                | Polymer  |
| Disc material                                      | Steel, galvanized  |
| Material of screws                                 | Galvanized steel   |
| Fuse material                                      | Spring steel, galvanized   |