


# Clevis flange SNCB-50

Part number: 174392

FESTO

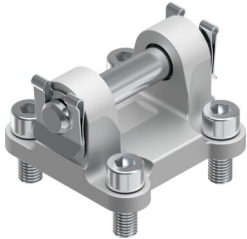

 [General operating condition](#)

## Data sheet

Feature	Value
Size	50
Based on norm	ISO 15552
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper are excluded from use. This excludes printed circuit boards, cables, electrical connectors and coils.
Ambient temperature	-40 °C ... 90 °C
Max. load capacity	2.5 kN
Product weight	233 g
Note on materials	RoHS compliant
Mounting material	Die-cast aluminum
Bolt material	Steel, galvanized
Material of bearing	Polymer
Disc material	Steel, galvanized
Material of screws	Galvanized steel
Fuse material	Spring steel, galvanized