


# Clevis flange SNCB-100

Part number: 174395

FESTO

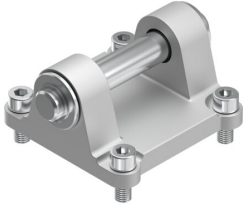

 [General operating condition](#)

## Data sheet

Feature	Value
Size	100
Based on norm	ISO 15552
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper are excluded from use. This excludes printed circuit boards, cables, electrical connectors and coils.
Ambient temperature	-40 °C ... 90 °C
Max. load capacity	9 kN
Product weight	1035 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Bolt material	Steel, galvanized
Material of bearing	Polymer
Disc material	Steel, galvanized
Material of screws	Steel, galvanized
Fuse material	Spring steel, galvanized