


Clevis flange SNCS-50

Part number: 174399

FESTO

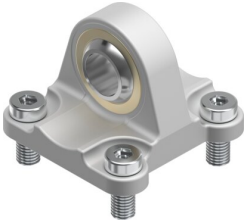

 [General operating condition](#)

Data sheet

| Feature | Value |
|----------------------------------|---|
| Size | 50 |
| Based on norm | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Ambient temperature | -40 °C ... 150 °C |
| Max. load capacity | 2.5 kN |
| Product weight | 216 g |
| Note on materials | RoHS-compliant |
| Mounting material | Die-cast aluminum |
| Rod end bearing material | Steel PTFE |
| Material of screws | Steel Galvanized |