


Clevis flange SNCS-50

Part number: 174399

FESTO

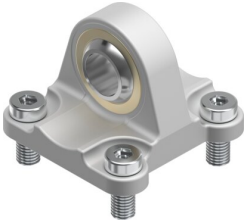

 [General operating condition](#)

Data sheet

Feature	Value
Size	50
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	2.5 kN
Product weight	216 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Rod end bearing material	Steel PTFE
Material of screws	Steel Galvanized