


# Clevis flange SNCS-100

Part number: 174402

FESTO

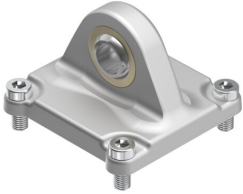

 [General operating condition](#)

## Data sheet

Feature	Value
Size	100
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	9 kN
Product weight	683 g
Note on materials	RoHS-compliant
Mounting material	Wrought aluminum alloy
Rod end bearing material	Steel PTFE
Material of screws	Steel Galvanized