


# Clevis flange SNCL-125

Part number: 174410

FESTO

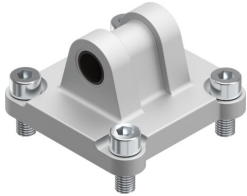

 [General operating condition](#)

## Data sheet

Feature	Value
Size	125
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 90 °C
Product weight	1135 g
Note on materials	RoHS-compliant
Mounting material	Die-cast aluminum
Material of bearing	Polymer
Material of screws	Steel Galvanized