


Pressure switch PEV-1/4-A-SW27-B-OD

Part number: 175252

FESTO

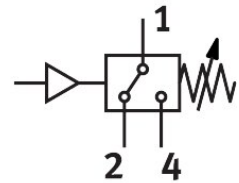

[PDF General operating condition](#)

Data sheet

Feature	Value
Symbol	00991472
CE marking (see declaration of conformity)	As per EU low voltage directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Measured variable	Relative pressure
Method of measurement	Pneumatic/electric pressure transducer
Operating pressure	1 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Temperature of medium	-20 °C ... 80 °C
Ambient temperature	-30 °C ... 100 °C
Switching element function	Changeover switch
Max. switching frequency	3 Hz
Max. switching output voltage AC	250 V
Max. switching output voltage DC	250 V
Max. output current	4000 mA
Electrical connection	4-pin Plug
Type of mounting	Screw-in
Mounting position	Any
Pneumatic connection	G1/4
Product weight	900 g
Housing material	PA66-GF30 Steel, galvanized
Diaphragm material	NBR
Setting range threshold value	1 bar ... 10 bar
Degree of protection	IP65
LABS (PWIS) conformity	VDMA24364-B1/B2-L