


# Distributor CQD-12/15/18/22

Part number: 177717

FESTO

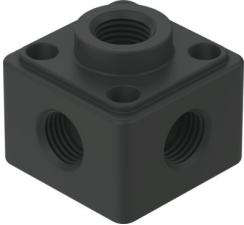

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal width	18.6 mm
Mounting position	Any
Pack size	1
Operating pressure for entire temperature range	-0.95 bar ... 7 bar
Temperature-dependent operating pressure	-0.95 bar ... 15 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Temperature of medium	-25 °C ... 75 °C
Ambient temperature	-25 °C ... 70 °C
Nominal tightening torque	2.5 Nm
Tolerance for nominal tightening torque	± 10%
No. of outlets	4
No. of supply lines	1
Pneumatic connection 1	Internal thread G1/2
Pneumatic connection 2	internal thread G1/2
Note on materials	RoHS-compliant
Housing material	POM