


# Service unit LFR-1/2-D-MAXI-KA

Part number: 186039

FESTO

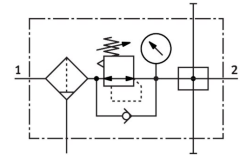

[PDF General operating condition](#)

## Data sheet

| Feature   | Value  |
|---|--|
| Size  | Maxi   |
| Series  | D  |
| Actuator lock                                     | Rotary knob with detent                                      |
| Mounting position                                 | Vertical $\pm 5^\circ$                                       |
| Grade of filtration                               | 40 $\mu\text{m}$   |
| Condensate drain                                  | Manual, rotating   |
| Structural design                                 | Branching module<br>Filter regulator with pressure gauge     |
| Max. condensate volume                            | 80 ml  |
| Bowl guard  | Metal bowl guard   |
| Symbol  | 00991770   |
| Pressure gauge                                    | with pressure gauge  |
| Operating pressure                                | 0.1 MPa ... 1.6 MPa  |
| Operating pressure                                | 1 bar ... 16 bar   |
| Operating pressure                                | 14.5 psi ... 232 psi   |
| Pressure regulation range MPa                     | 0.05 MPa ... 1.2 MPa   |
| Pressure regulation range                         | 0.5 bar ... 12 bar   |
| Pressure regulation range psi                     | 7.25 psi ... 174 psi   |
| Max. pressure hysteresis                          | 0.02 MPa   |
| Max. pressure hysteresis                          | 0.2 bar  |
| Max. pressure hysteresis                          | 2.9 psi  |
| Normal nominal flow rate (normalized to DIN 1343) | 9200 l/min   |
| Operating medium                                  | Inert gases  |
| Corrosion resistance class (CRC)                  | 2 - Moderate corrosion stress                                |
| LABS (PWIS) conformity                            | VDMA24364-B1/B2-L  |
| Air quality class at the output                   | Compressed air as per ISO 8573-1:2010 [7:8:4]<br>Inert gases |
| Temperature of medium                             | -10 $^\circ\text{C}$ ... 60 $^\circ\text{C}$                 |
| Ambient temperature                               | -10 $^\circ\text{C}$ ... 60 $^\circ\text{C}$                 |
| Product weight                                    | 2400 g   |
| Type of mounting                                  | With accessories   |
| Pneumatic connection 1                            | G1/2   |
| Pneumatic connection 2                            | G1/2   |
| Housing material                                  | Die-cast zinc  |
| Material of bowl                                  | PC   |