


# Cable socket ASI-SD-FK

Part number: 18785

FESTO

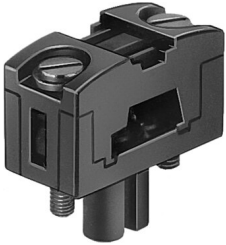

 [General operating condition](#)

## Data sheet

| Feature  | Value                    |
|--|--------------------------|
| Type of mounting                                     | With through-hole        |
| Mounting position                                    | Any                      |
| Product weight                                       | 6.8 g                    |
| Electrical connection                                | 2-pin<br>Straight socket |
| DC operating voltage range                           | ≤75 V                    |
| Operating voltage range AC                           | ≤60 V                    |
| Current rating                                       | 3 A                      |
| Connection cross section                             | 1.5 mm <sup>2</sup>      |
| Degree of protection                                 | IP65                     |
| Ambient temperature with flexible cable installation | -5 °C ... 50 °C          |
| Storage temperature                                  | -30 °C ... 85 °C         |
| LABS (PWIS) conformity                               | VDMA24364-B2-L           |
| Note on materials                                    | RoHS compliant           |
| Housing material                                     | PA                       |
| Material of pin contacts                             | Bronze                   |