


# Cable socket ASI-SD-FK

Part number: 18785

FESTO

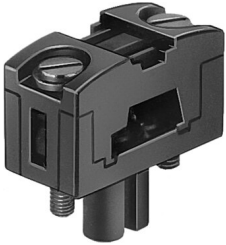

 [General operating condition](#)

## Data sheet

Feature	Value
Type of mounting	With through-hole
Mounting position	Any
Product weight	6.8 g
Electrical connection	2-pin Socket, straight
DC operating voltage range	≤75 V
Operating voltage range AC	≤60 V
Current rating	3 A
Connection cross section	1.5 mm <sup>2</sup>
Degree of protection	IP65
Ambient temperature with flexible cable installation	-5 °C ... 50 °C
Storage temperature	-30 °C ... 85 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Housing material	PA
Material of pin contacts	Bronze