


# Vacuum suction cup holder ESH-HE-4-G1/8

Part number: 189256

FESTO

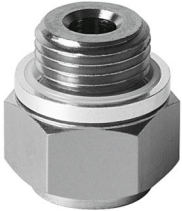

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal width	4 mm
Volume	0.289 cm <sup>3</sup>
Mounting position	Any
Structural design	Vacuum connection at top
Classification of suction cup holder	Size 4
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-A1-L
Ambient temperature	-10 °C ... 60 °C
Product weight	11 g
Type of mounting	With external thread Via vacuum connection
Suction cup mounting	M6
Vacuum connection	G1/8
Note on materials	RoHS compliant
Seals material	Wrought aluminum alloy NBR POM Steel
Retainer bracket material	Quenched and tempered steel