


Power supply module VABF-C8-12-P3A5-QX

Part number: 1894888

FESTO

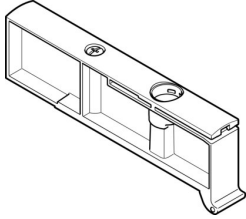

 [General operating condition](#)

Data sheet

Feature	Value
Operating pressure	0 MPa ... 0.8 MPa
Operating pressure	0 bar ... 8 bar
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	-5 °C ... 60 °C
Ambient temperature	-5 °C ... 60 °C
Product weight	13.8 g
Pneumatic connection 1	Prepared for cartridge
Note on materials	RoHS-compliant
Housing material	PA-reinforced