


# Plug socket with cable KMF-1-24-10-LED

Part number: 193458

FESTO

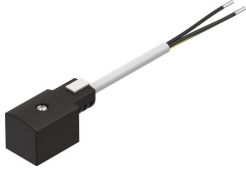

 [General operating condition](#)

## Data sheet

Feature	Value
Switching position indication	LED
Type of mounting	On air solenoid valve with M3 central screw
Mounting position	Any
Product weight	620 g
Electrical connection	Socket
Nominal operating voltage DC	24 V
Protective earth connection	Available
Cable length	10 m
Cable diameter	6 mm
Cable design	3 x 0.75 mm <sup>2</sup>
Degree of protection	IP67 as per IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Material of cable sheath	PVC
Housing material	PC POM
Material of pin contacts	Bronze