


# Mounting plate VN-T4-BP-NRH

Part number: 195279

FESTO

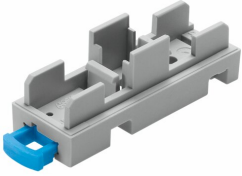

 [General operating condition](#)

## Data sheet

Feature	Value
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	0 °C ... 60 °C
Max. tightening torque	0.5 Nm
Product weight	4.5 g
Type of mounting	With through-hole With DIN rail
Plate material	Reinforced POM
Gate valve material	POM