


# Manifold MHA1-P6-2-M3

Part number: 197209

FESTO

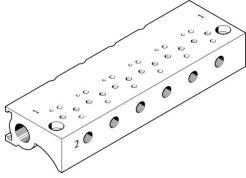

 [General operating condition](#)

## Data sheet

| Feature                                  | Value                                                              |
|------------------------------------------|--------------------------------------------------------------------|
| Max. no. of valve positions              | 6                                                                  |
| Operating pressure                       | 0 bar ... 8 bar                                                    |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)         | 1 - Low corrosion stress                                           |
| LABS (PWIS) conformity                   | VDMA24364-B2-L                                                     |
| Ambient temperature                      | -10 °C ... 60 °C                                                   |
| Sub-base mounting type                   | With through-hole                                                  |
| Pneumatic valve mounting type            | With internal thread                                               |
| Pneumatic connection 1                   | M7                                                                 |
| Pneumatic connection 2                   | M3                                                                 |
| Material of sub-base                     | Wrought aluminum alloy                                             |