


# Manifold MHA1-PR8-3-M3-PI-PCB

Part number: 197250

FESTO

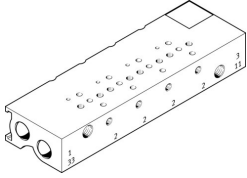

 [General operating condition](#)

## Data sheet

Feature	Value
Max. no. of valve positions	8
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	0 °C ... 40 °C
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M5
Pneumatic connection 2	M3
Pneumatic connection 3	M5
Material of sub-base	Wrought aluminum alloy