


Distributor block FR-8-1/8

Part number: 2077

FESTO

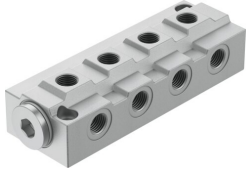

 [General operating condition](#)

Data sheet

Feature	Value
Nominal width	8.6 mm
Mounting position	Any
Operating pressure for entire temperature range	0 bar ... 16 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Nominal tightening torque	12.5 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	135 g
No. of outlets	8
No. of supply lines	1
Pneumatic connection 1	Internal thread G3/8
Pneumatic connection 2	Internal thread G1/8
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum