


Clevis foot LBG-32-R3

Part number: 2078790

FESTO

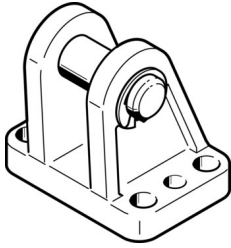

 [General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Size | 32 |
| Mounting position | Any |
| Corrosion resistance class (CRC) | 3 - High corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. The exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils. |
| Ambient temperature | -40 °C ... 150 °C |
| Max. load capacity | 0.9 kN |
| Product weight | 220 g |
| Note on materials | RoHS compliant |
| Mounting material | high-alloy stainless steel |
| Bolt material | high-alloy stainless steel |
| Fuse material | high-alloy stainless steel |