


Clevis foot LBG-32-R3

Part number: 2078790

FESTO

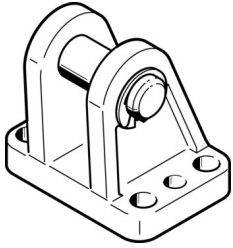

 [General operating condition](#)

Data sheet

Feature	Value
Size	32
Mounting position	Any
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. The exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils.
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	0.9 kN
Product weight	220 g
Note on materials	RoHS-compliant
Mounting material	High-alloy stainless steel
Bolt material	High-alloy stainless steel
Fuse material	High-alloy stainless steel