


Parallel kit EAMM-U-50-S38-40P-78

Part number: 2155239

FESTO

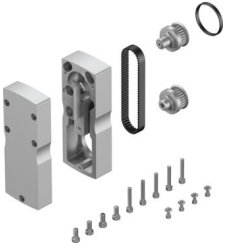

 [General operating condition](#)

Data sheet

Feature	Value
Size	50
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	12.1 kgmm ²
No-load driving torque	0.01 Nm
Transferable torque	1 Nm
Product weight	577 g
Interface code, actuator	S38
Interface code, motor in	40P
Note on materials	RoHS-compliant